


## KN25-B-PP

### Linear ball bearing

Schaeffler ID:  
0173755410000

Linear ball bearings KN...-B-PP, Lightweight range, closed design, sealed on all sides, with relubrication facility, adjustable angle

## Technical information

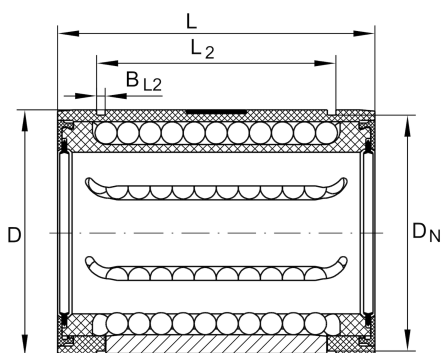

### Main Dimensions & Performance Data

$F_w$	25 mm	Bore diameter of ball complement
$D$	40 mm	Outside diameter
$L$	58 mm	length
$C_{min}$	3.100 N	load capacity dyn.
$C_{0 min}$	2.220 N	load capacity stat.
$C_{max}$	3.250 N	load capacity dyn.
$C_{0 max}$	2.850 N	load capacity stat.
	0,135 kg	Weight

### Mounting dimensions

$L_2$	43,7 mm	
$B_{L2}$	1,85 mm	
$D_N$	38,5 mm	
$T_4$	1,4 mm	
$N_4$	3 mm	
$b_{1 max}$	2,5 mm	
	6	Number of rows balls

