


KN40-B-PP

Linear ball bearing

Schaeffler ID:
0244636800000

Linear ball bearings KN...-B-PP, Lightweight range, closed design, sealed on all sides, with relubrication facility, adjustable angle

Technical information

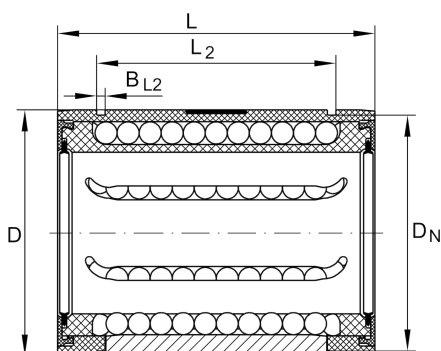

Main Dimensions & Performance Data

F_w	40 mm	Bore diameter of ball complement
D	62 mm	Outside diameter
L	80 mm	length
C_{min}	6.300 N	load capacity dyn.
$C_{0 min}$	4.350 N	load capacity stat.
C_{max}	6.700 N	load capacity dyn.
$C_{0 max}$	5.600 N	load capacity stat.
	0,374 kg	Weight

Mounting dimensions

L_2	60,3 mm	
B_{L2}	2,15 mm	
D_N	59,4 mm	
T_4	2,2 mm	
N_4	3 mm	
$b_{1 max}$	3 mm	
	6	Number of rows balls

