


KSO16-PP

Linear ball bearing

Schaeffler ID:
0067536980000

Linear ball bearings KSO...-PP, heavy load range, lip seals on both sides

Technical information

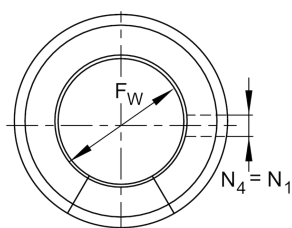



KS16, 20
KSO16, 20


Main Dimensions & Performance Data

F_w	16 mm	Bore diameter of ball complement
D	26 mm	Outside diameter
L	36 mm	length
C_{max}	1.430 N	load capacity dyn.
C_{0max}	1.550 N	load capacity stat.
	21,39 g	Weight

Mounting dimensions

B_2	10,1 mm	Width of sector opening
N_1	3 mm	
N_4	3 mm	
α	78 °	Angle of sector opening
	6	Number of rows balls

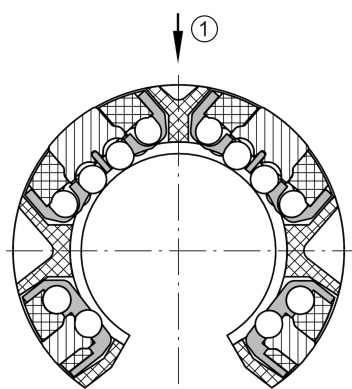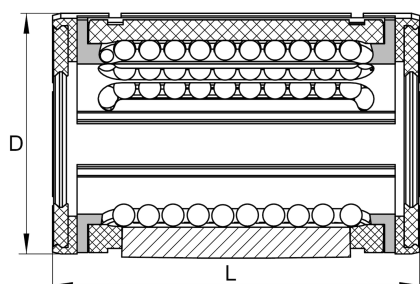

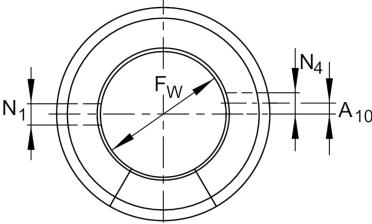

KS30, 40, 50
KSO30, 40, 50

