



## KNO12-B

### Linear ball bearing

Schaeffler ID:  
0296807190000

Linear ball bearings KNO..-B, Lightweight range, open design, with relubrication facility, adjustable angle

### Technical information

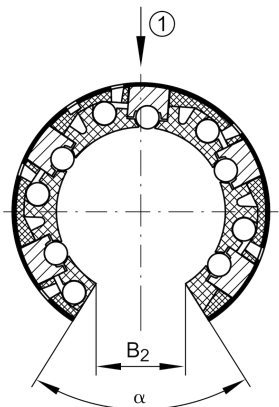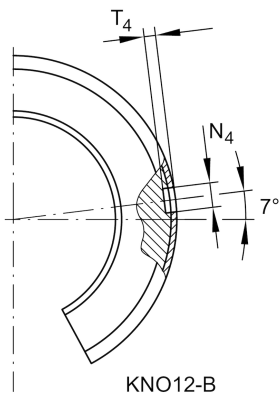

### Main Dimensions & Performance Data

$F_w$	12 mm	Bore diameter of ball complement
$D$	22 mm	Outside diameter
$L$	32 mm	length
$C_{max}$	840 N	load capacity dyn.
$C_{0max}$	640 N	load capacity stat.
	20 g	Weight

### Mounting dimensions

$B_2$	6,5 mm	Width of sector opening
$T_4$	0,7 mm	
$N_4$	3 mm	
$\alpha$	66 °	Angle of sector opening
$b_{1max}$	1,5 mm	
	4	Number of rows balls

