



KNO30-B

Linear ball bearing

Schaeffler ID:
0296807940000

Linear ball bearings KNO..-B, Lightweight range, open design, with relubrication facility, adjustable angle

Technical information

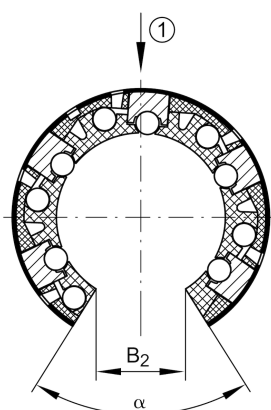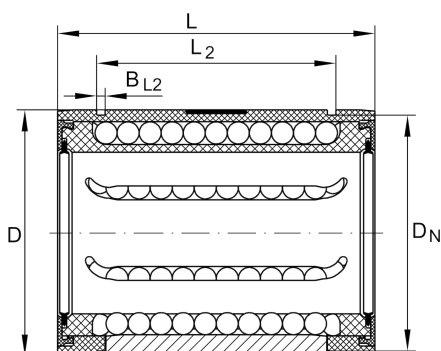

Main Dimensions & Performance Data

F_w	30 mm	Bore diameter of ball complement
D	47 mm	Outside diameter
L	68 mm	length
C_{max}	3.750 N	load capacity dyn.
C_{0max}	2.850 N	load capacity stat.
	0,159 kg	Weight

Mounting dimensions

B_2	14 mm	Width of sector opening
T_4	2,2 mm	
A_{10}	2 mm	Angle of sector opening
N_4	3 mm	
α	57 °	Angle of sector opening
b_{1max}	2,5 mm	
	5	Number of rows balls

