




Technical information

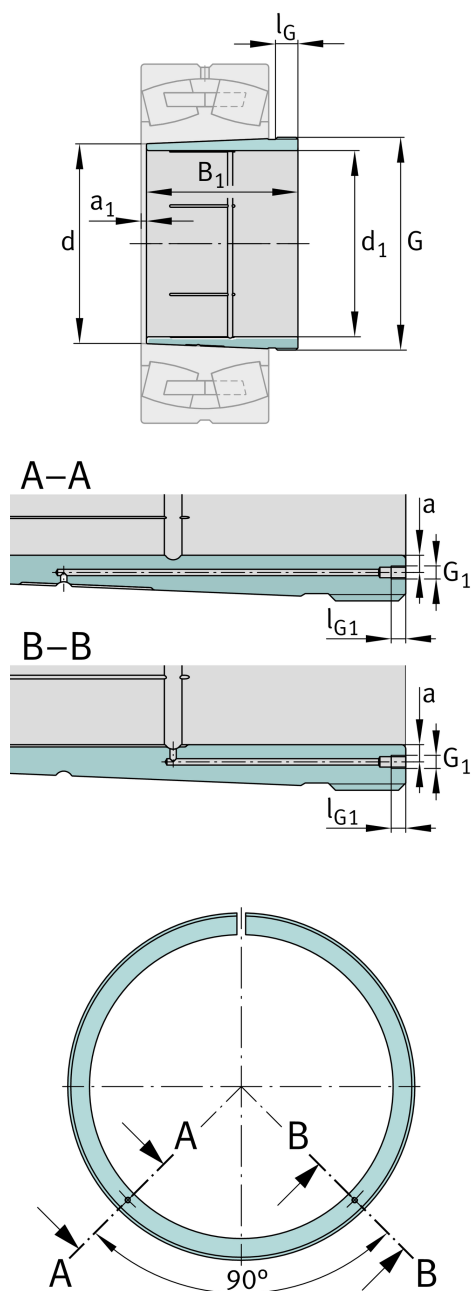

Main Dimensions & Performance Data

d_1	260 mm	bore diameter
G	Tr300X4	Thread
B_1	202 mm	sleeve length
	16,9 kg	Weight

Dimensions

d	280 mm	Bore diameter
a_1	17 mm	Bearing overhang
l_G	22 mm	Thread length
	1:30	Taper

Mounting dimensions

G_1	G1/8	Thread oil connector
a	8,5 mm	Distance oil connector
l_{G1}	12 mm	Thread depth oil connector