



FAG

52318

Axial deep groove ball bearing

Schaeffler ID:  
0190659140000Axial deep groove ball bearing 523, double  
direction, steel sheet metal cage

## Technical information

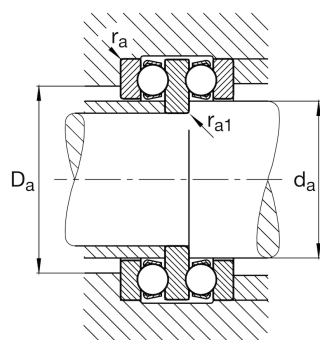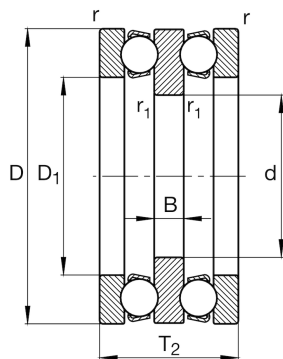

## Main Dimensions &amp; Performance Data

d	75 mm	Bore diameter
D	155 mm	Outside diameter
T <sub>2</sub>	88 mm	Height
C <sub>a</sub>	193.000 N	Basic dynamic load rating, axial
C <sub>0a</sub>	455.000 N	Basic static load rating, axial
C <sub>ua</sub>	18.800 N	Fatigue load limit, axial
n <sub>G</sub>	2.240 1/min	Limiting speed
n <sub>gr</sub>	3.900 1/min	Reference speed
	6,463 kg	Weight

## Additional information

D <sub>1</sub>	93 mm	Bore diameter housing washer
B	19 mm	Height shaft washer
r <sub>min</sub>	1,5 mm	Minimum chamfer dimension
r <sub>1 min</sub>	1 mm	Minimum chamfer dimension

## Mounting dimensions

d <sub>a max</sub>	90 mm	Maximum mounting dimension shaft
D <sub>a max</sub>	116 mm	Maximum diameter of housing shoulder
r <sub>a max</sub>	1,5 mm	Maximum recess radius
r <sub>a1 max</sub>	1 mm	Maximum recess radius

## Calculation factors

A	1,2	Minimum load factor
---	-----	---------------------

## Temperature range

T <sub>min</sub>	-30 °C	Operating temperature min.
T <sub>max</sub>	150 °C	Operating temperature max.