



BE25-XL


Deep groove ball bearing

Schaeffler ID:
0009494260000

Radial insert ball bearings BE, cylindrical outer ring, with steel aligning ring, P seals on both sides

X-life

Technical information

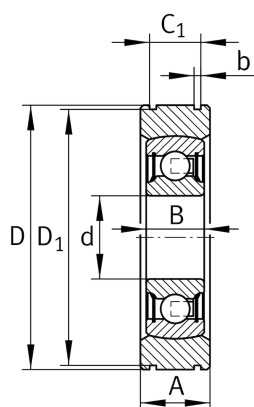

Main Dimensions & Performance Data

d	25 mm	Bore diameter
D	62 mm	Outside diameter
C_r	14.000 N	Basic dynamic load rating, radial
C_{0r}	7.800 N	Basic static load rating, radial
C_{ur}	410 N	Fatigue load limit, radial
	0,24 kg	Weight

Dimensions

	205-XL-NPP-B	Bearing designation
A	17 mm	Width, outer ring
C_1	11,2 mm	Distance ring grooves
	0,2 mm	Upper distance ring groove tolerance
b	1,9 mm	Width retaining slot
	0,3 mm	Nut width upper tolerance
D_1	59,6 mm	Diameter of groove
	-0,5 mm	Nut diameter lower tolerance

Calculation factors

f_0	13,8	Calculation factor
-------	------	--------------------