

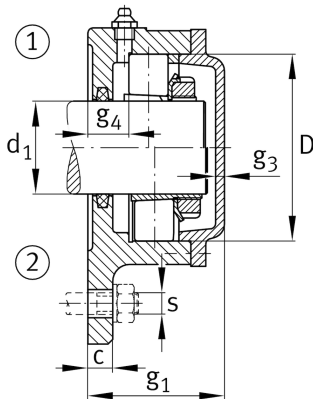
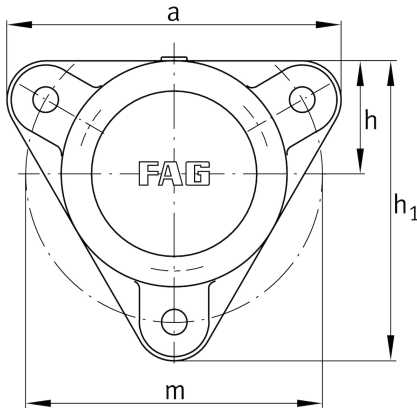
**FAG**★ **F508-A-L**

Flanged housing

Schaeffler ID:
0384386740000Flanged housing for various bearing types,
with conical bore and clamping sleeve,
closed on one side

★ Preferred product

Technical information

**Main Dimensions & Performance Data**

d_1	35 mm	Shaft diameter
a	160 mm	Flange width
h_1	143 mm	height flange
g_2	65 mm	total width with cover
	3	number of fastening holes
	2,7 kg	Weight

Dimensions

	M10x1	connection thread lubrication
c	12 mm	thickness of flange
D	80 mm	outside diameter bearing
g_4	22 mm	distance flange to bearing seat
h	54 mm	distance shaft axis
m	140 mm	pitch circle diameter fixing holes
s	M12	size of fixing screws