

**FAG**★ **F508-WB-L**

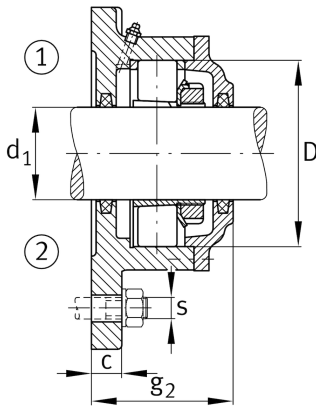
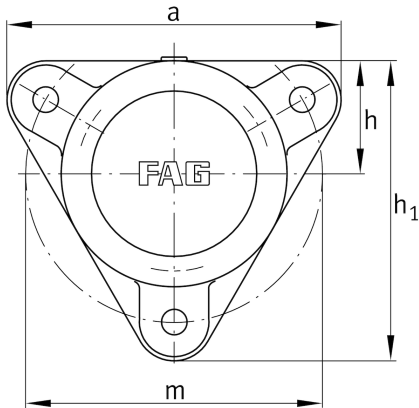
Flanged housing

Schaeffler ID:  
0383829380000

★ Preferred product

Flanged housing for various bearing types, wide version with conical bore and clamping sleeve, continuous shaft

## Technical information

**Main Dimensions & Performance Data**

$d_1$	35 mm	Shaft diameter
$a$	160 mm	Flange width
$h_1$	143 mm	height flange
$g_2$	71 mm	total width with cover
	3	number of fastening holes
	2,9 kg	Weight

**Dimensions**

	M10x1	connection thread lubrication
$c$	12 mm	thickness of flange
$D$	80 mm	outside diameter bearing
$g_4$	22 mm	distance flange to bearing seat
$h$	54 mm	distance shaft axis
$m$	140 mm	pitch circle diameter fixing holes
$s$	M12	size of fixing screws