

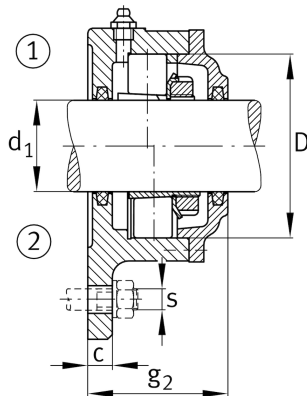
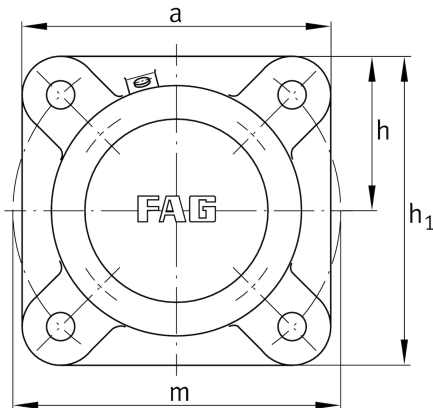
**FAG**★ **F515-B-L**

Flanged housing

Schaeffler ID:
0383830550000Flanged housing for various bearing types,
with conical bore and clamping sleeve,
continuous shaft

★ Preferred product

Technical information

**Main Dimensions & Performance Data**

d_1	65 mm	Shaft diameter
a	190 mm	Flange width
h_1	190 mm	height flange
g_2	104 mm	total width with cover
	4	number of fastening holes
	9,5 kg	Weight

Dimensions

	M10x1	connection thread lubrication
c	25 mm	thickness of flange
D	130 mm	outside diameter bearing
g_4	30 mm	distance flange to bearing seat
h	95 mm	distance shaft axis
m	215 mm	pitch circle diameter fixing holes
s	M16	size of fixing screws