

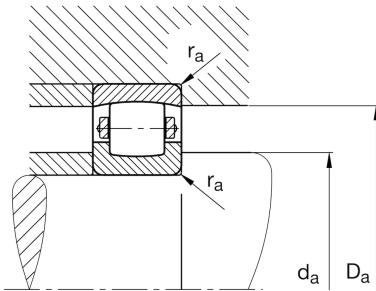
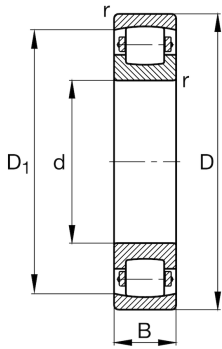
FAG

20322-MB

Barrel roller bearing

Schaeffler ID:
0190143250000Barrel roller bearings 203, main
dimensions to DIN 635-1

Technical information

**Temperature range**

T_{\min}	-30 °C	Operating temperature min.
T_{\max}	200 °C	Operating temperature max.
	11,8 kg	Weight

Main Dimensions & Performance Data

d	110 mm	Bore diameter
D	240 mm	Outside diameter
B	50 mm	Width
C_r	405.000 N	Basic dynamic load rating, radial
C_{0r}	480.000 N	Basic static load rating, radial
C_{ur}	46.000 N	Fatigue load limit, radial
n_G	3.000 1/min	Limiting speed

Dimensions

r_{\min}	3 mm	Minimum chamfer dimension
D_1	208,1 mm	Bore diameter outer ring

Mounting dimensions

$d_{a \min}$	124 mm	Minimum diameter shaft shoulder
$D_{a \max}$	226 mm	Maximum diameter of housing shoulder
$r_{a \max}$	2,5 mm	Maximum recess radius