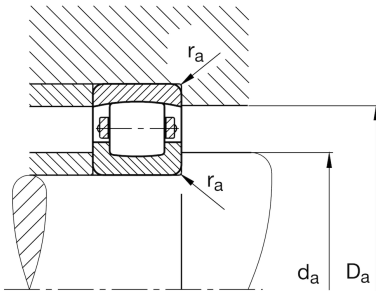
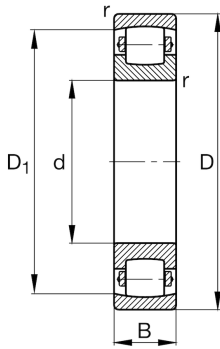
**FAG****20324-MB**

Barrel roller bearing

Schaeffler ID:
0190143330000Barrel roller bearings 203, main
dimensions to DIN 635-1

Technical information

**Temperature range**

T_{\min}	-30 °C	Operating temperature min.
T_{\max}	200 °C	Operating temperature max.
	15,1 kg	Weight

Main Dimensions & Performance Data

d	120 mm	Bore diameter
D	260 mm	Outside diameter
B	55 mm	Width
C_r	490.000 N	Basic dynamic load rating, radial
C_{0r}	630.000 N	Basic static load rating, radial
C_{ur}	52.000 N	Fatigue load limit, radial
n_G	2.750 1/min	Limiting speed

Dimensions

r_{\min}	3 mm	Minimum chamfer dimension
D_1	222,3 mm	Bore diameter outer ring

Mounting dimensions

$d_{a \min}$	134 mm	Minimum diameter shaft shoulder
$D_{a \max}$	246 mm	Maximum diameter of housing shoulder
$r_{a \max}$	2,5 mm	Maximum recess radius