





K23X35X16-TV

Needle roller cage assembly

Schaeffler ID:
0007030606063

Needle roller cage assembly K..-TV, single
row

Technical information

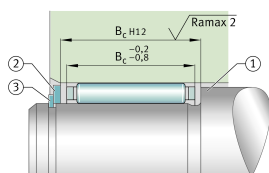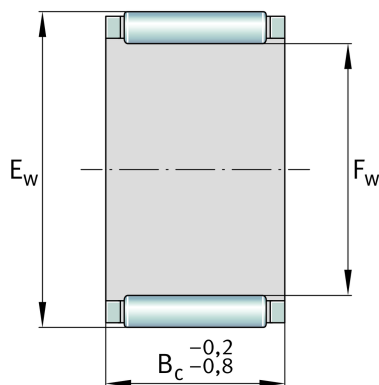

Main Dimensions & Performance Data

F_w	23 mm	Inner diameter of needle roller complement
E_w	35 mm	Outside diameter of needle roller complement
B_c	16 mm	Width
C_r	24.500 N	Basic dynamic load rating, radial
C_{0r}	23.900 N	Basic static load rating, radial
C_{ur}	3.050 N	Fatigue load limit, radial
n_G	16.900 1/min	Limiting speed
n_{gr}	9.500 1/min	Reference speed
	30,1 g	Weight

Temperature range

T_{min}	-20 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.