

FAG



★ 2311-2RS-TVH

Self-aligning ball bearing

Schaeffler ID:
0167074350000Self-aligning ball bearing 23...-2RS-TVH,
seals, plastic cage

★ Preferred product

Technical information

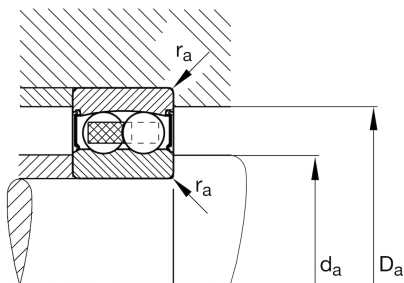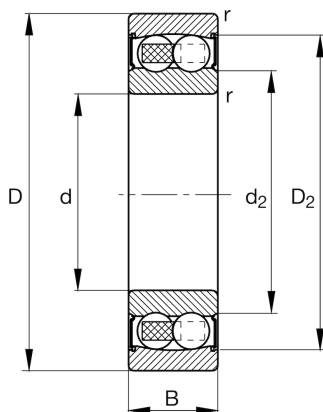

Temperature range

T_{\min}	-20 °C	Operating temperature min.
T_{\max}	100 °C	Operating temperature max.
	1,886 kg	Weight

Main Dimensions & Performance Data

d	55 mm	Bore diameter
D	120 mm	Outside diameter
B	43 mm	Width
r_{\min}	2 mm	Minimum chamfer dimension
C_r	52.000 N	Basic dynamic load rating, radial
C_{0r}	17.900 N	Basic static load rating, radial
C_{ur}	1.130 N	Fatigue load limit, radial
n_G	3.450 1/min	Limiting speed

Dimensions

D_2	106,4 mm	Caliber diameter outer ring
d_2	70,5 mm	Caliber diameter inner ring

Mounting dimensions

$d_{a \min}$	66 mm	Minimum diameter shaft shoulder
$D_{a \max}$	109 mm	Maximum diameter of housing shoulder
$r_{a \max}$	2 mm	Maximum fillet radius

Calculation factors

e	0,24	Limiting value of F_a/F_r for the applicability of diff. Values of factors X and Y
Y_1	2,65	Dynamic axial load factor
Y_2	4,1	Dynamic axial load factor
Y_0	2,78	Static axial load factor