

FAG


★ 51126

Axial deep groove ball bearing

Schaeffler ID:
0167148650000Axial deep groove ball bearing 511, single
direction, steel sheet metal cage

★ Preferred product

Technical information

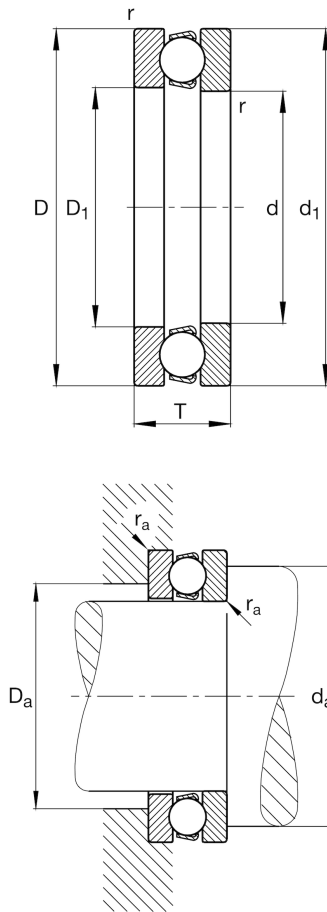

Temperature range

T_{\min}	-30 °C	Operating temperature min.
T_{\max}	150 °C	Operating temperature max.
	1,757 kg	Weight

Main Dimensions & Performance Data

d	130 mm	Bore diameter
D	170 mm	Outside diameter
T	30 mm	Height
C_a	111.000 N	Basic dynamic load rating, axial
C_{0a}	390.000 N	Basic static load rating, axial
C_{ua}	14.600 N	Fatigue load limit, axial
n_G	2.850 1/min	Limiting speed
n_{gr}	2.490 1/min	Reference speed

Dimensions

r_{\min}	1 mm	Minimum chamfer dimension
D_1	132 mm	Bore diameter housing washer
d_1	170 mm	Lip diameter shaft washer

Mounting dimensions

$d_{a\min}$	154 mm	Minimum diameter shaft shoulder
$D_{a\max}$	146 mm	Maximum diameter of housing shoulder
$r_{a\max}$	1 mm	Maximum recess radius

Additional information

A	0,76	Minimum load factor
---	------	---------------------