

**FAG**★ **6008-2Z**

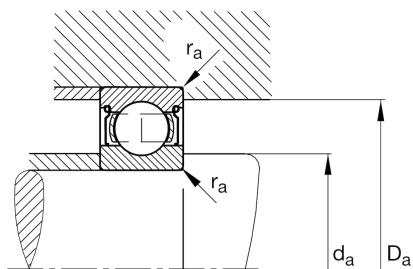
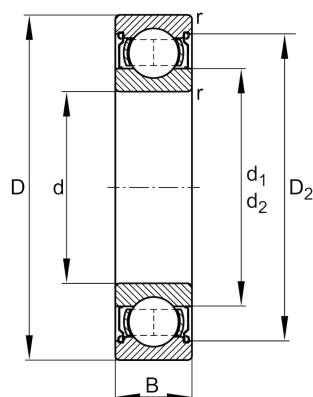
Deep groove ball bearing

Schaeffler ID:
0167175460000

Deep groove ball bearing 60...-2Z, single row, shields, steel sheet metal cage

★ Preferred product

Technical information

**Temperature range**

T_{\min}	-20 °C	Operating temperature min.
T_{\max}	120 °C	Operating temperature max.
	0,189 kg	Weight

Main Dimensions & Performance Data

d	40 mm	Bore diameter
D	68 mm	Outside diameter
B	15 mm	Width
C_r	17.800 N	Basic dynamic load rating, radial
C_{0r}	11.500 N	Basic static load rating, radial
C_{ur}	600 N	Fatigue load limit, radial
n_G	12.400 1/min	Limiting speed
n_{gr}	10.600 1/min	Reference speed

Dimensions

r_{\min}	1 mm	Minimum chamfer dimension
D_2	61,6 mm	Caliber diameter outer ring
d_1	49,3 mm	Shoulder diameter inner ring

Mounting dimensions

$d_{a\min}$	44,6 mm	Minimum diameter shaft shoulder
$D_{a\max}$	63,4 mm	Maximum diameter of housing shoulder
$r_{a\max}$	1 mm	Maximum fillet radius

Calculation factors

f_0	15,2	Calculation factor
-------	------	--------------------