



**FAG**★ **62211-2RSR**

Deep groove ball bearing

Schaeffler ID:  
0167218610000Deep groove ball bearing 622..-2RSR,  
single row, seals, steel sheet metal cage

★ Preferred product

## Technical information

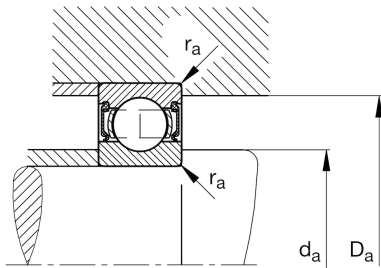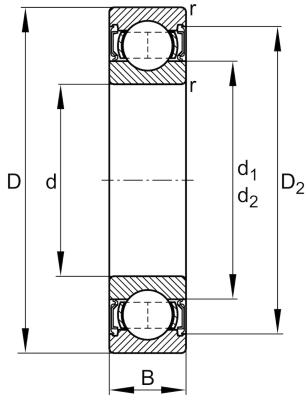

## Temperature range

$T_{\min}$	-20 °C	Operating temperature min.
$T_{\max}$	110 °C	Operating temperature max.
	0,72 kg	Weight

## Main Dimensions &amp; Performance Data

$d$	55 mm	Bore diameter
$D$	100 mm	Outside diameter
$B$	25 mm	Width
$C_r$	44.500 N	Basic dynamic load rating, radial
$C_{0r}$	29.000 N	Basic static load rating, radial
$C_{ur}$	1.770 N	Fatigue load limit, radial
$n_G$	3.900 1/min	Limiting speed

## Dimensions

$r_{\min}$	1,5 mm	Minimum chamfer dimension
$D_2$	88,2 mm	Caliber diameter outer ring
$d_1$	68,7 mm	Shoulder diameter inner ring

## Mounting dimensions

$d_{a \min}$	64 mm	Minimum diameter shaft shoulder
$D_{a \max}$	91 mm	Maximum diameter of housing shoulder
$r_{a \max}$	1,5 mm	Maximum fillet radius

## Calculation factors

$f_0$	14,2	Calculation factor
-------	------	--------------------