

FAG

## ★ 7307-B-XL-TVP


Angular contact ball bearing

Schaeffler ID:  
0167259640000Angular contact ball bearing 73..-B-XL-  
TVP, single row, X-life, plastic cage

★ Preferred product

X-life

## Technical information

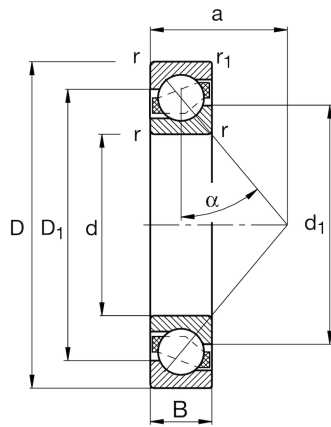

## Temperature range

$T_{\min}$	-30 °C	Operating temperature min.
$T_{\max}$	120 °C	Operating temperature max.
	0,466 kg	Weight

## Main Dimensions &amp; Performance Data

$d$	35 mm	Bore diameter
$D$	80 mm	Outside diameter
$B$	21 mm	Width
$C_r$	45.500 N	Basic dynamic load rating, radial
$C_{0r}$	27.500 N	Basic static load rating, radial
$C_{ur}$	1.910 N	Fatigue load limit, radial
$n_G$	11.900 1/min	Limiting speed
$n_{gr}$	7.900 1/min	Reference speed

## Dimensions

$r_{\min}$	1,5 mm	Minimum chamfer dimension
$r_{1\min}$	1 mm	Minimum chamfer dimension
$D_1$	63 mm	Shoulder diameter on outer ring wide side face
$d_1$	53,1 mm	Shoulder diameter on inner ring wide side face
$a$	35 mm	Distance between the apexes of the pressure cones
$\alpha$	40 °	Contact angle

## Mounting dimensions

$d_{a\min}$	44 mm	Minimum diameter of shaft shoulder
$D_{a\max}$	71 mm	Maximum diameter of housing shoulder
$D_{b\max}$	74,4 mm	Maximaler Durchmesser der Gehäuseschulter
$r_{a\max}$	1,5 mm	Maximum fillet radius of shaft
$r_{a1\max}$	1 mm	Maximum fillet radius of housing

