



FAG

★ 7208-B-XL-JP


Angular contact ball bearing

Schaeffler ID:
0191147960000Angular contact ball bearing 72..-B-XL-JP,
single row, X-life, steel sheet metal cage

★ Preferred product

X-life

Technical information

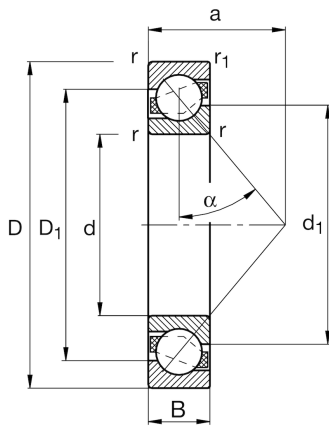

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	150 °C	Operating temperature max.
	0,004 kg	Weight

Main Dimensions & Performance Data

d	40 mm	Bore diameter
D	80 mm	Outside diameter
B	18 mm	Width
C_r	36.000 N	Basic dynamic load rating, radial
C_{0r}	23.500 N	Basic static load rating, radial
C_{ur}	1.630 N	Fatigue load limit, radial
n_G	11.900 1/min	Limiting speed
n_{gr}	8.600 1/min	Reference speed

Dimensions

r_{min}	1,1 mm	Minimum chamfer dimension
r_{1min}	0,6 mm	Minimum chamfer dimension
D_1	64,4 mm	Shoulder diameter on outer ring wide side face
d_1	56,4 mm	Shoulder diameter on inner ring wide side face
a	34 mm	Distance between the apexes of the pressure cones
α	40 °	Contact angle

Mounting dimensions

d_{amin}	47 mm	Minimum diameter of shaft shoulder
D_{amax}	73 mm	Maximum diameter of housing shoulder
D_{bmax}	75,8 mm	Maximaler Durchmesser der Gehäuseschulter
r_{amax}	1 mm	Maximum fillet radius of shaft
r_{a1max}	0,6 mm	Maximum fillet radius of housing

