**FAG**★ **623-2Z**

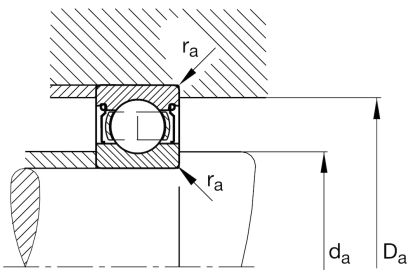
Deep groove ball bearing

Schaeffler ID:  
0383908680000

Deep groove ball bearing 62...-2Z, single row, shields, steel sheet metal cage

★ Preferred product

## Technical information

**Temperature range**

$T_{\min}$	-30 °C	Operating temperature min.
$T_{\max}$	120 °C	Operating temperature max.
	2 g	Weight

**Main Dimensions & Performance Data**

d	3 mm	Bore diameter
D	10 mm	Outside diameter
B	4 mm	Width
$C_r$	670 N	Basic dynamic load rating, radial
$C_{0r}$	218 N	Basic static load rating, radial
$C_{ur}$	11,7 N	Fatigue load limit, radial
$n_G$	81.000 1/min	Limiting speed
$n_{gr}$	59.000 1/min	Reference speed

**Dimensions**

$r_{\min}$	0,15 mm	Minimum chamfer dimension
$D_2$	7,98 mm	Caliber diameter outer ring
$d_2$	4,35 mm	Caliber diameter inner ring

**Mounting dimensions**

$d_{a\min}$	4,4 mm	Minimum diameter shaft shoulder
$D_{a\max}$	8,6 mm	Maximum diameter of housing shoulder
$r_{a\max}$	0,15 mm	Maximum fillet radius

**Calculation factors**

$f_0$	12,3	Calculation factor
-------	------	--------------------