**FAG**★ **F11206**

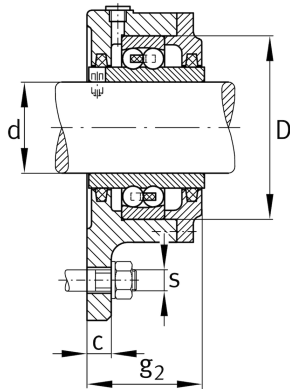
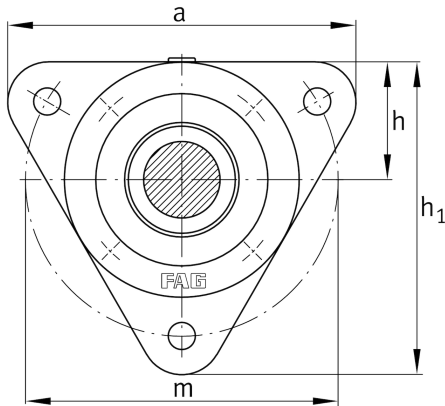
Flanged housing

Schaeffler ID:
0383828490000

Flanged housing for self-aligning ball bearing 112 with wide inner-ring, felt seal, grease lubrication

★ Preferred product

Technical information

**Main Dimensions & Performance Data**

d	30 mm	Shaft diameter
a	130 mm	Flange width
g ₂	49 mm	Total width with cover
h ₁	117 mm	Height flange
	1,35 kg	Weight

Dimensions

	M10x1 M	Connection thread for lubrication
c	12 mm	Thickness of flange
D	62 mm	Outside diameter bearing
h	44 mm	Distance shaft axis
m	116 mm	Pitch circle diameter fixing holes
s	M10 m	Size of fixing screws