

FAG



## ★ 20204-TVP

Barrel roller bearing

Schaeffler ID:  
0167017120000Barrel roller bearings 202, main  
dimensions to DIN 635-1

★ Preferred product

## Technical information

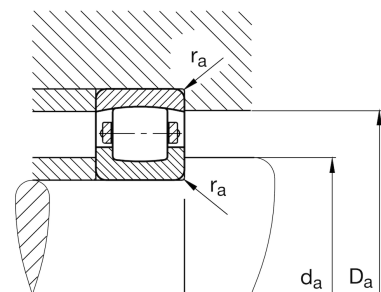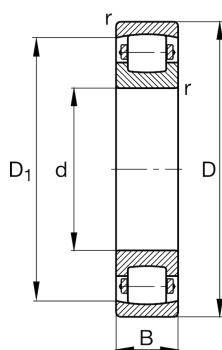

## Temperature range

$T_{\min}$	-30 °C	Operating temperature min.
$T_{\max}$	120 °C	Operating temperature max.
	0,111 kg	Weight

## Main Dimensions &amp; Performance Data

d	20 mm	Bore diameter
D	47 mm	Outside diameter
B	14 mm	Width
$C_r$	20.400 N	Basic dynamic load rating, radial
$C_{0r}$	19.400 N	Basic static load rating, radial
$C_{ur}$	1.730 N	Fatigue load limit, radial
$n_G$	13.100 1/min	Limiting speed

## Dimensions

$r_{\min}$	1 mm	Minimum chamfer dimension
$D_1$	39 mm	Bore diameter outer ring

## Mounting dimensions

$d_{a \min}$	25,6 mm	Minimum diameter shaft shoulder
$D_{a \max}$	41,4 mm	Maximum diameter of housing shoulder
$r_{a \max}$	1 mm	Maximum recess radius