

**FAG**★ **20210-TVP**

Barrel roller bearing

Schaeffler ID:
0167018010000Barrel roller bearings 202, main
dimensions to DIN 635-1

★ Preferred product

Technical information

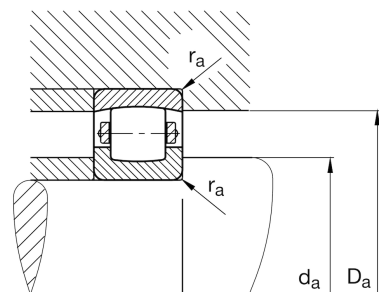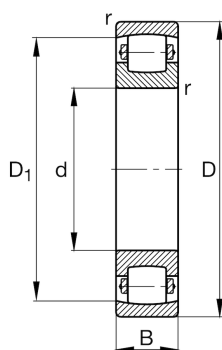

Temperature range

T_{\min}	-30 °C	Operating temperature min.
T_{\max}	120 °C	Operating temperature max.
	0,481 kg	Weight

Main Dimensions & Performance Data

d	50 mm	Bore diameter
D	90 mm	Outside diameter
B	20 mm	Width
C_r	59.000 N	Basic dynamic load rating, radial
C_{0r}	69.000 N	Basic static load rating, radial
C_{ur}	7.200 N	Fatigue load limit, radial
n_G	7.700 1/min	Limiting speed

Dimensions

r_{\min}	1,1 mm	Minimum chamfer dimension
D_1	79,5 mm	Bore diameter outer ring

Mounting dimensions

$d_{a \min}$	57 mm	Minimum diameter shaft shoulder
$D_{a \max}$	83 mm	Maximum diameter of housing shoulder
$r_{a \max}$	1 mm	Maximum recess radius