

FAG



★ 20216-TVP

Barrel roller bearing

Schaeffler ID:
0167019330000Barrel roller bearings 202, main
dimensions to DIN 635-1

★ Preferred product

Technical information

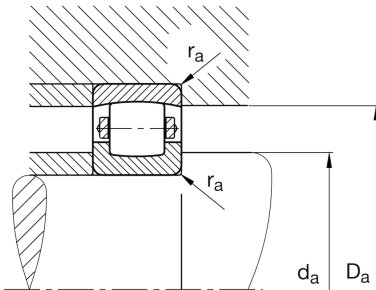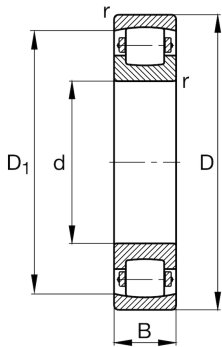

Temperature range

T_{\min}	-30 °C	Operating temperature min.
T_{\max}	120 °C	Operating temperature max.
	1,519 kg	Weight

Main Dimensions & Performance Data

d	80 mm	Bore diameter
D	140 mm	Outside diameter
B	26 mm	Width
C_r	126.000 N	Basic dynamic load rating, radial
C_{0r}	163.000 N	Basic static load rating, radial
C_{ur}	15.900 N	Fatigue load limit, radial
n_G	5.200 1/min	Limiting speed

Dimensions

r_{\min}	2 mm	Minimum chamfer dimension
D_1	124,5 mm	Bore diameter outer ring

Mounting dimensions

$d_{a \min}$	91 mm	Minimum diameter shaft shoulder
$D_{a \max}$	129 mm	Maximum diameter of housing shoulder
$r_{a \max}$	2 mm	Maximum recess radius