

FAG



## ★ 20314-MB

Barrel roller bearing

Schaeffler ID:  
0190142010000Barrel roller bearings 203, main  
dimensions to DIN 635-1

★ Preferred product

## Technical information

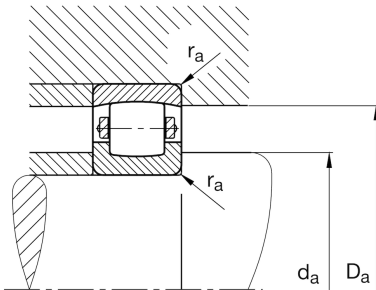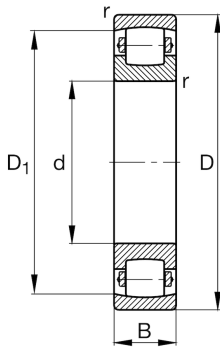

## Temperature range

$T_{\min}$	-30 °C	Operating temperature min.
$T_{\max}$	200 °C	Operating temperature max.
	3,135 kg	Weight

## Main Dimensions &amp; Performance Data

d	70 mm	Bore diameter
D	150 mm	Outside diameter
B	35 mm	Width
$C_r$	184.000 N	Basic dynamic load rating, radial
$C_{0r}$	215.000 N	Basic static load rating, radial
$C_{ur}$	19.900 N	Fatigue load limit, radial
$n_G$	4.450 1/min	Limiting speed

## Dimensions

$r_{\min}$	2,1 mm	Minimum chamfer dimension
$D_1$	128,7 mm	Bore diameter outer ring

## Mounting dimensions

$d_{a \min}$	82 mm	Minimum diameter shaft shoulder
$D_{a \max}$	138 mm	Maximum diameter of housing shoulder
$r_{a \max}$	2,1 mm	Maximum recess radius