

FAG

★ 20213-K-TVP-C3



Barrel roller bearing

Schaeffler ID:
0384287410030

Barrel roller bearing 202...-K-TVP

★ Preferred product

Technical information

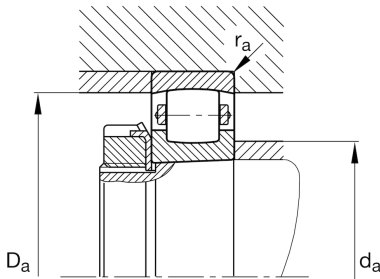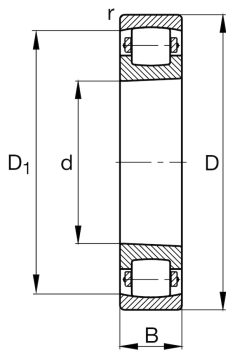

Temperature range

T_{\min}	-30 °C	Operating temperature min.
T_{\max}	120 °C	Operating temperature max.
	1,045 kg	Weight

Main Dimensions & Performance Data

d	65 mm	Bore diameter
D	120 mm	Outside diameter
B	23 mm	Width
C_r	94.000 N	Basic dynamic load rating, radial
C_{0r}	117.000 N	Basic static load rating, radial
C_{ur}	12.700 N	Fatigue load limit, radial
n_G	6.000 1/min	Limiting speed

Dimensions

r_{\min}	1,5 mm	Minimum chamfer dimension
D_1	105,1 mm	Bore diameter outer ring

Mounting dimensions

$d_{a \min}$	74 mm	Minimum diameter shaft shoulder
$D_{a \max}$	111 mm	Maximum diameter of housing shoulder
$r_{a \max}$	1,5 mm	Maximum recess radius
$d_{a \max}$	80 mm	Maximum diameter of shaft shoulder
$d_{b \min}$	70 mm	Minimum cavity diameter of the sleeve
$B_{a \min}$	5 mm	Minimum cavity width of the sleeve

Additional information

H213	Adapter sleeve
------	----------------