

★ NA4908-2RSR-XL

Needle roller bearing


Schaeffler ID:
0507752430000

Needle roller bearings NA49...-2RSR,
dimension series 49, lip seals on both
sides

★ Preferred product

X-life

Technical information

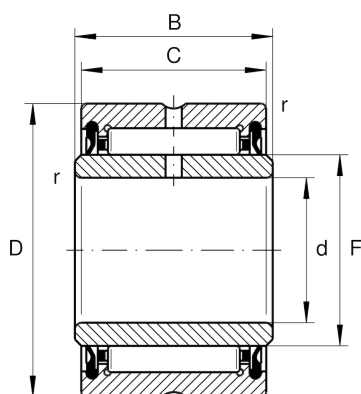

Temperature range

T_{\min}	-20 °C	Operating temperature min.
T_{\max}	100 °C	Operating temperature max.
	0,002 kg	Weight

Main Dimensions & Performance Data

d	40 mm	Bore diameter
D	62 mm	Outside diameter
B	23 mm	Width, inner ring
C_r	41.000 N	Basic dynamic load rating, radial
C_{0r}	53.000 N	Basic static load rating, radial
C_{ur}	9.000 N	Fatigue load limit, radial
$n_{G \text{ Grease}}$	5.500 1/min	Limiting speed for grease lubrication

Dimensions

F	48 mm	Raceway diameter inner ring
C	22 mm	Width, outer ring
r_{\min}	0,6 mm	Minimum chamfer dimension