

★ NA6915-ZW-XL

Needle roller bearing



Schaeffler ID:
0507442750000

Needle roller bearings NA69...ZW,
Dimension series 69, double row

★ Preferred product

X-life

Technical information

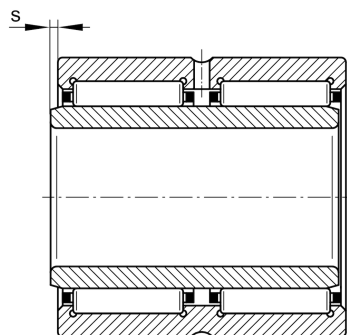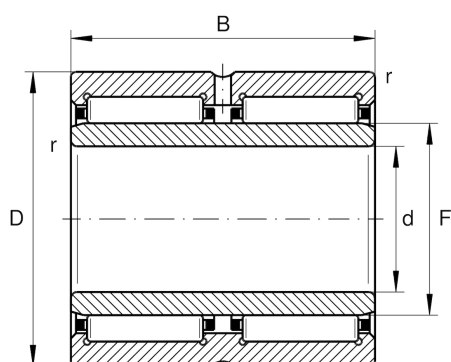

Temperature range

T_{\min}	-30 °C	Operating temperature min.
T_{\max}	120 °C	Operating temperature max.
	1,41 kg	Weight

Main Dimensions & Performance Data

d	75 mm	Bore diameter
D	105 mm	Outside diameter
B	54 mm	Width
C_r	147.000 N	Basic dynamic load rating, radial
C_{0r}	275.000 N	Basic static load rating, radial
C_{ur}	50.000 N	Fatigue load limit, radial
n_G	5.400 1/min	Limiting speed
n_{gr}	3.150 1/min	Reference speed

Dimensions

F	85 mm	Raceway diameter inner ring
r_{\min}	1 mm	Minimum chamfer dimension
s	1 mm	Axial displacement