

★ NK32/20-TV-XL

Needle roller bearing


Schaeffler ID:
0507542030000

Needle roller bearings NK, light series

★ Preferred product

X-life

Technical information

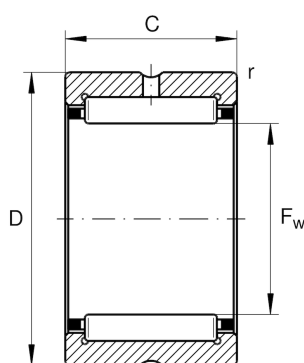

Temperature range

T_{\min}	-20 °C	Operating temperature min.
T_{\max}	120 °C	Operating temperature max.
	0,063 kg	Weight

Main Dimensions & Performance Data

F_w	32 mm	Under roller diameter
D	42 mm	Outside diameter
C	20 mm	Width, outer ring
C_r	29.500 N	Basic dynamic load rating, radial
C_{0r}	44.500 N	Basic static load rating, radial
C_{ur}	8.000 N	Fatigue load limit, radial
n_G	14.000 1/min	Limiting speed
n_{gr}	8.000 1/min	Reference speed

Dimensions

r_{\min}	0,3 mm	Minimum chamfer dimension
------------	--------	---------------------------

Additional information

G32X42X4	Sealing ring
SD32X42X4	Sealing ring 2