

★ NK50/35-TV-XL

Needle roller bearing


Schaeffler ID:
0507543940000

Needle roller bearings NK, light series

★ Preferred product

X-life

Technical information

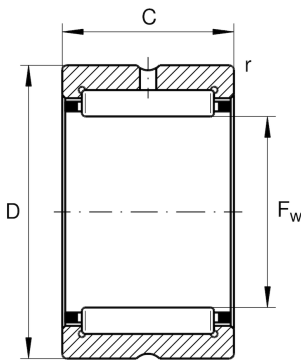

Temperature range

T_{\min}	-20 °C	Operating temperature min.
T_{\max}	120 °C	Operating temperature max.
	0,002 kg	Weight

Main Dimensions & Performance Data

F_w	50 mm	Under roller diameter
D	62 mm	Outside diameter
C	35 mm	Width, outer ring
C_r	67.000 N	Basic dynamic load rating, radial
C_{0r}	132.000 N	Basic static load rating, radial
C_{ur}	24.300 N	Fatigue load limit, radial
n_G	9.200 1/min	Limiting speed
n_{gr}	5.200 1/min	Reference speed

Dimensions

r_{\min}	0,6 mm	Minimum chamfer dimension
------------	--------	---------------------------

Additional information

G50X62X5	Sealing ring
SD50X62X5	Sealing ring 2