

★ NK65/25-XL

Needle roller bearing


Schaeffler ID:
0507545480000

Needle roller bearings NK, light series

★ Preferred product

X-life

Technical information

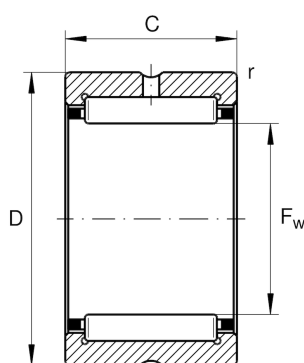

Temperature range

T_{\min}	-30 °C	Operating temperature min.
T_{\max}	120 °C	Operating temperature max.
	0,002 kg	Weight

Main Dimensions & Performance Data

F_w	65 mm	Under roller diameter
D	78 mm	Outside diameter
C	25 mm	Width, outer ring
C_r	50.000 N	Basic dynamic load rating, radial
C_{0r}	98.000 N	Basic static load rating, radial
C_{ur}	17.000 N	Fatigue load limit, radial
n_G	7.200 1/min	Limiting speed
n_{gr}	4.500 1/min	Reference speed

Dimensions

r_{\min}	0,6 mm	Minimum chamfer dimension
------------	--------	---------------------------