**NK68/25-XL**

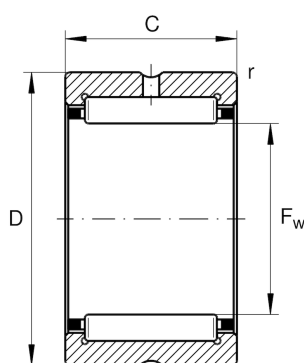
Needle roller bearing

Schaeffler ID:
0507545640000

Needle roller bearings NK, light series

X-life

Technical information

**Main Dimensions & Performance Data**

F_w	68 mm	Under roller diameter
D	82 mm	Outside diameter
C	25 mm	Width, outer ring
C_r	49.500 N	Basic dynamic load rating, radial
C_{0r}	89.000 N	Basic static load rating, radial
C_{ur}	15.500 N	Fatigue load limit, radial
n_G	6.800 1/min	Limiting speed
n_{gr}	4.500 1/min	Reference speed
	0,002 kg	Weight

Additional information

r_{min}	0,6 mm	Minimum chamfer dimension
-----------	--------	---------------------------

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.