**NK73/35-XL**

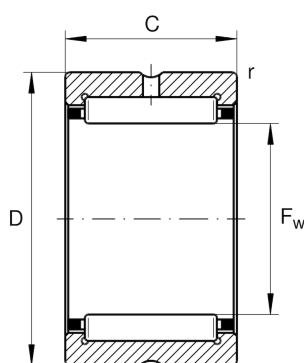
Needle roller bearing

Schaeffler ID:
0507546100000

Needle roller bearings NK, light series

X-life

Technical information

**Main Dimensions & Performance Data**

F_w	73 mm	Under roller diameter
D	90 mm	Outside diameter
C	35 mm	Width, outer ring
C_r	85.000 N	Basic dynamic load rating, radial
C_{0r}	156.000 N	Basic static load rating, radial
C_{ur}	27.500 N	Fatigue load limit, radial
n_G	6.300 1/min	Limiting speed
n_{gr}	4.050 1/min	Reference speed
	0,429 kg	Weight

Additional information

r_{min}	1 mm	Minimum chamfer dimension
-----------	------	---------------------------

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.