



★ NKI20/20-XL

Needle roller bearing



Schaeffler ID:
0507620100000

Needle roller bearings NKI, light series

★ Preferred product

X-life

Technical information

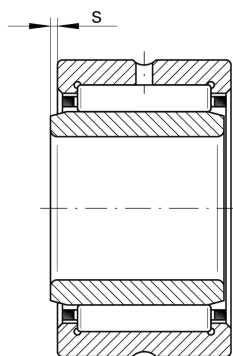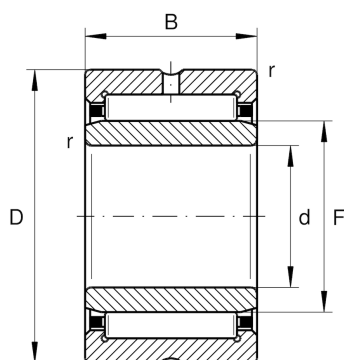

Temperature range

T_{\min}	-30 °C	Operating temperature min.
T_{\max}	120 °C	Operating temperature max.
	61,3 g	Weight

Main Dimensions & Performance Data

d	20 mm	Bore diameter
D	32 mm	Outside diameter
B	20 mm	Width
C_r	21.400 N	Basic dynamic load rating, radial
C_{0r}	30.500 N	Basic static load rating, radial
C_{ur}	8.100 N	Fatigue load limit, radial
n_G	18.500 1/min	Limiting speed
n_{gr}	8.600 1/min	Reference speed

Dimensions

F	24 mm	Raceway diameter inner ring
r_{\min}	0,3 mm	Minimum chamfer dimension
s	0,5 mm	Axial displacement