



## ★ NKI32/20-XL

Needle roller bearing



Schaeffler ID:  
0507622060000

Needle roller bearings NKI, light series

★ Preferred product

X-life

### Technical information

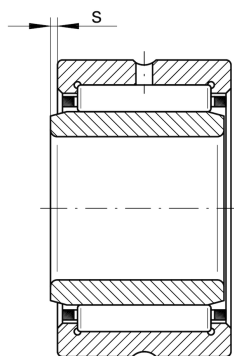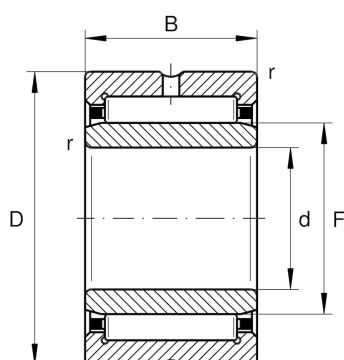

#### Temperature range

$T_{\min}$	-30 °C	Operating temperature min.
$T_{\max}$	120 °C	Operating temperature max.
	0,117 kg	Weight

#### Main Dimensions & Performance Data

d	32 mm	Bore diameter
D	47 mm	Outside diameter
B	20 mm	Width
$C_r$	28.000 N	Basic dynamic load rating, radial
$C_{0r}$	43.500 N	Basic static load rating, radial
$C_{ur}$	7.800 N	Fatigue load limit, radial
$n_G$	12.300 1/min	Limiting speed
$n_{gr}$	6.900 1/min	Reference speed

#### Dimensions

F	37 mm	Raceway diameter inner ring
$r_{\min}$	0,3 mm	Minimum chamfer dimension
s	0,5 mm	Axial displacement