



★ NKI35/20-TV-XL

Needle roller bearing



Schaeffler ID:
0507622220000

Needle roller bearings NKI, light series

★ Preferred product

X-life

Technical information

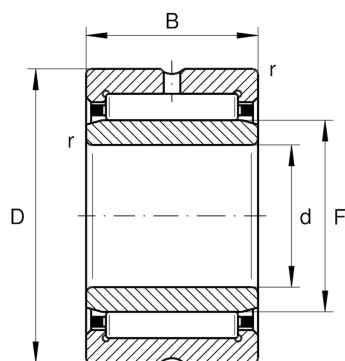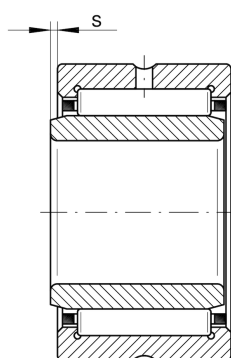

Temperature range

T_{\min}	-20 °C	Operating temperature min.
T_{\max}	120 °C	Operating temperature max.
	0,121 kg	Weight

Main Dimensions & Performance Data

d	35 mm	Bore diameter
D	50 mm	Outside diameter
B	20 mm	Width
C_r	33.500 N	Basic dynamic load rating, radial
C_{0r}	56.000 N	Basic static load rating, radial
C_{ur}	10.000 N	Fatigue load limit, radial
n_G	11.400 1/min	Limiting speed
n_{gr}	6.100 1/min	Reference speed

Dimensions

F	40 mm	Raceway diameter inner ring
r_{\min}	0,3 mm	Minimum chamfer dimension
s	0,5 mm	Axial displacement