

**NKI5/16-TV-XL**

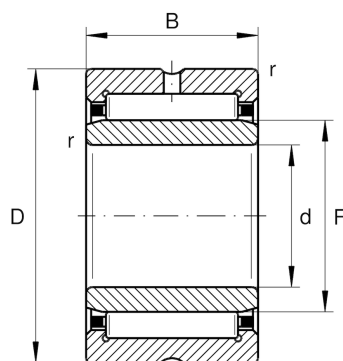
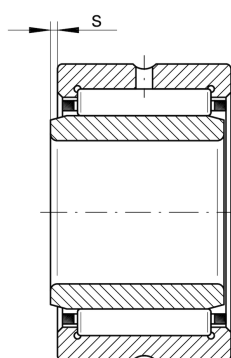
Needle roller bearing

Schaeffler ID:
0507614550000

Needle roller bearings NKI, light series

X-life

Technical information

**Main Dimensions & Performance Data**

d	5 mm	Bore diameter
D	15 mm	Outside diameter
B	16 mm	Width
C_r	5.800 N	Basic dynamic load rating, radial
C_{0r}	5.800 N	Basic static load rating, radial
C_{ur}	990 N	Fatigue load limit, radial
n_G	32.500 1/min	Limiting speed
n_{gr}	32.000 1/min	Reference speed
	15,3 g	Weight

Dimensions

F	8 mm	Raceway diameter inner ring
r_{min}	0,3 mm	Minimum chamfer dimension
s	2 mm	Axial displacement

Temperature range

T_{min}	-20 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.