

## RNAO25X35X26-ZW-ASR1-XL




Needle roller bearing

Schaeffler ID:  
0507759280000

Needle roller bearings RNAO...-ZW-ASR1,  
without ribs, double row

X-life

### Technical information

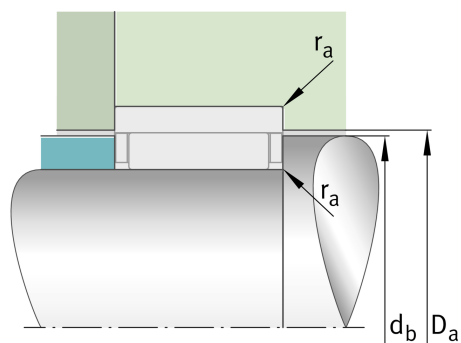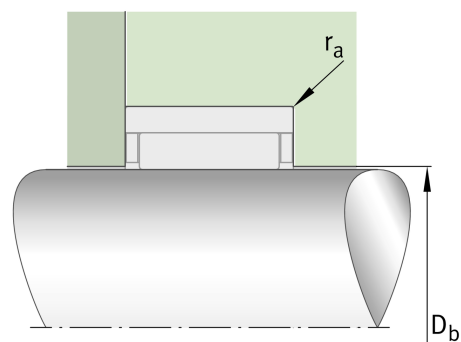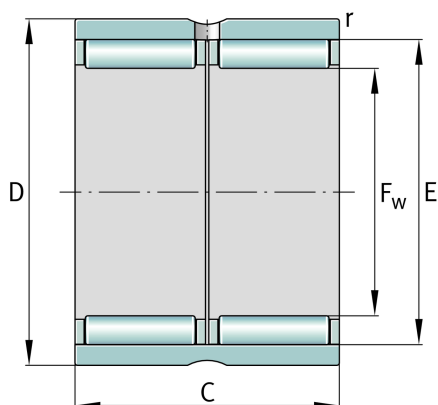

### Main Dimensions & Performance Data

$F_w$	25 mm	Under roller diameter
$D$	35 mm	Outside diameter
$C$	26 mm	Width, outer ring
$C_r$	21.900 N	Basic dynamic load rating, radial
$C_{0r}$	37.000 N	Basic static load rating, radial
$C_{ur}$	6.100 N	Fatigue load limit, radial
$n_G$	18.100 1/min	Limiting speed
$n_{gr}$	11.200 1/min	Reference speed
	0,076 kg	Weight

### Dimensions

$E$	29 mm	Raceway diameter outer ring
$r_{min}$	0,3 mm	Minimum chamfer dimension

### Mounting dimensions

$D_b$	25,6 mm	Shoulder diameter axial guidance NK/housing
$d_b$	28,4 mm	Shoulder diameter axial guidance NK/shaft
$D_a$	29,5 mm	Shoulder diameter outer ring
$r_{a max}$	0,3 mm	Maximum recess radius

### Temperature range

$T_{min}$	-30 °C	Operating temperature min.
$T_{max}$	120 °C	Operating temperature max.