

RNAO35X47X32-ZW-ASR1-XL




Needle roller bearing

Schaeffler ID:
0507760290000

Needle roller bearings RNAO...-ZW-ASR1,
without ribs, double row

X-life

Technical information

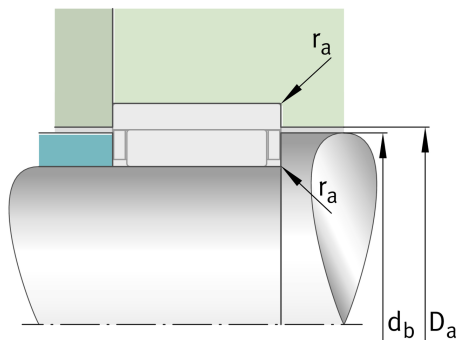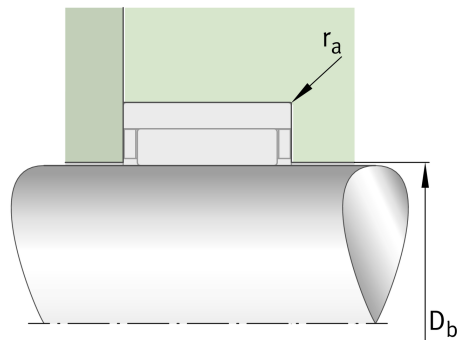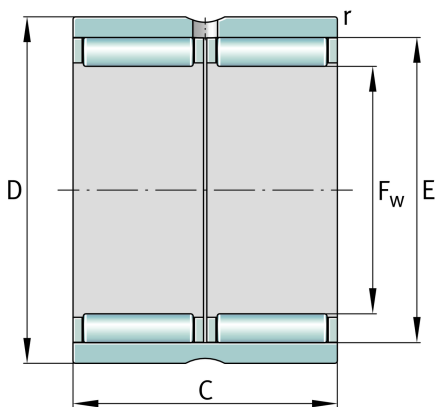

Main Dimensions & Performance Data

F_w	35 mm	Under roller diameter
D	47 mm	Outside diameter
C	32 mm	Width, outer ring
C_r	47.500 N	Basic dynamic load rating, radial
C_{0r}	75.000 N	Basic static load rating, radial
C_{ur}	12.600 N	Fatigue load limit, radial
n_G	12.700 1/min	Limiting speed
n_{gr}	7.500 1/min	Reference speed
	0,156 kg	Weight

Dimensions

E	42 mm	Raceway diameter outer ring
r_{min}	0,3 mm	Minimum chamfer dimension

Mounting dimensions

D_b	35,6 mm	Shoulder diameter axial guidance NK/housing
d_b	41,4 mm	Shoulder diameter axial guidance NK/shaft
D_a	42,5 mm	Shoulder diameter outer ring
$r_{a max}$	0,3 mm	Maximum recess radius

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.