




## ★ NKIA5904-XL

Needle roller/angular contact ball bearing

Schaeffler ID:  
0504211400000

★ Preferred product

### Technical information

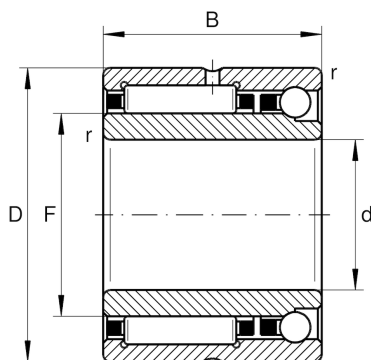

#### Main Dimensions & Performance Data

d	20 mm	Bore diameter
D	37 mm	Outside diameter
B	23 mm	Width
$C_r$	23.700 N	Basic dynamic load rating, radial
$C_{0r}$	25.500 N	Basic static load rating, radial
$C_a$	4.900 N	Basic dynamic load rating, axial
$C_{0a}$	7.400 N	Basic static load rating, axial
$C_{ur}$	4.700 N	Fatigue limit load, radial
$C_{ur}$	4.700 N	Fatigue load limit, radial
$C_{ua}$	335 N	Fatigue load limit, axial
$n_G$	17.200 1/min	Limiting speed
$n_{gr}$	14.000 1/min	Reference speed
	0,001 kg	Weight

#### Dimensions

F	25 mm	Raceway diameter inner ring
$r_{min}$	0,3 mm	Minimum chamfer dimension