



★ AXK110145-A/0-10

Axial needle roller and cage assembly


Schaeffler ID:
0000358079065

Axial needle roller and cage assemblies,
single direction, to DIN 5405-2

★ Preferred product

Technical information

Main Dimensions & Performance Data

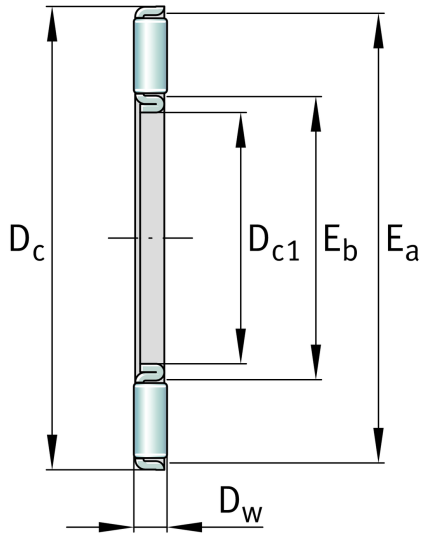

D_{c1}	110 mm	Bore diameter cage
D_c	145 mm	Outside diameter
D_w	4 mm	Rolling element diameter
E_a	143 mm	Raceway dimension
E_b	115 mm	Raceway dimension
c_a	97.000 N	Basic dynamic load rating, axial
c_{0a}	620.000 N	Basic static load rating, axial
c_{ua}	64.000 N	Fatigue load limit, axial
n_G	2.260 1/min	Limiting speed
n_{gr}	890 N	Reference speed
	0,001 kg	Weight

Additional information

AS110145	Axial bearing washer
----------	----------------------

