

IR15X19X16-XL


Inner ring

Schaeffler ID:
0000208260000

Inner ring IR..-XL, cylindrical

X-life

Technical information

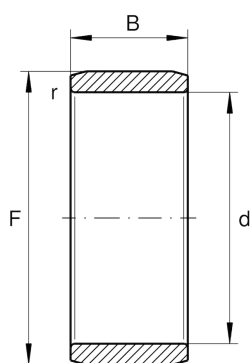

Main Dimensions & Performance Data

d	15 mm	Bore diameter
F	19 mm	Raceway diameter inner ring
B	16 mm	Width
	0 mm	Raceway diameter upper tolerance
	-0,012 mm	Raceway diameter lower tolerance
r _{min}	0,3 mm	Minimum chamfer dimension
	0,013 kg	Weight