

★ IR40X50X20-IS1-XL

Inner ring


Schaeffler ID:
0000223730000

Inner rings IR...IS1, precision machined,
with lubrication hole, to DIN 620

★ Preferred product

X-life

Technical information

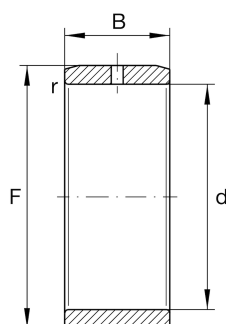

Main Dimensions & Performance Data

d	40 mm	Bore diameter
F	50 mm	Raceway diameter inner ring
B	20 mm	Width
	0 mm	Raceway diameter upper tolerance
	-0,009 mm	Raceway diameter lower tolerance
r _{min}	1 mm	Minimum chamfer dimension
	0,106 kg	Weight

Mounting dimensions

	1	Number of lubrication holes
--	---	-----------------------------