

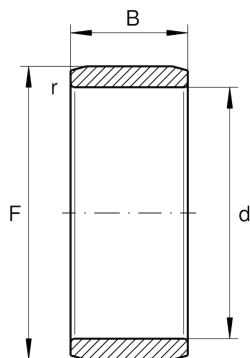
**LR20X25X16,5**

Inner ring

Schaeffler ID:
0000212100000

Inner ring LR, cylindrical

Technical information

**Main Dimensions & Performance Data**

d	20 mm	Bore diameter
F	25 mm	Raceway diameter inner ring
B	16,5 mm	Width
r _{min}	0,3 mm	Minimum chamfer dimension
	30 °	Chamfer angle
	22,3 g	Weight