

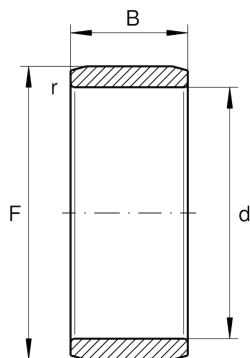
**LR20X25X20,5**

Inner ring

Schaeffler ID:
0000597220000

Inner ring LR, cylindrical

Technical information

**Main Dimensions & Performance Data**

d	20 mm	Bore diameter
F	25 mm	Raceway diameter inner ring
B	20,5 mm	Width
r_{\min}	0,3 mm	Minimum chamfer dimension
	30 °	Chamfer angle
	0,028 kg	Weight