



## ★ LR45X50X20,5


Inner ring

Schaeffler ID:  
0000599000000

Inner ring LR, cylindrical

★ Preferred product

### Technical information

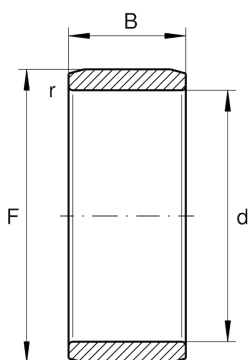

#### Main Dimensions & Performance Data

d	45 mm	Bore diameter
F	50 mm	Raceway diameter inner ring
B	20,5 mm	Width
r <sub>min</sub>	0,3 mm	Minimum chamfer dimension
	30 °	Chamfer angle
	58,9 g	Weight