



★ AY30-XL-NPP-B

Radial insert ball bearing


Schaeffler ID:
0038073550000

★ Preferred product

Radial insert ball bearings AY..-NPP-B, spherical outer ring, location by grub screws, P seals on both sides

X-life

Technical information

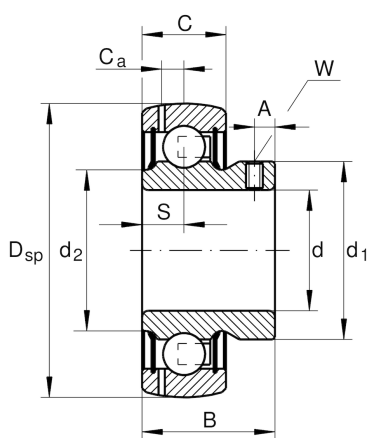

Main Dimensions & Performance Data

d	30 mm	Bore diameter
D _{SP}	62 mm	Outside diameter
B	30 mm	Width
n _{G Grease}	13.800 1/min	Limiting speed for grease lubrication
C _r	19.500 N	Basic dynamic load rating, radial
C _{0r}	11.300 N	Basic static load rating, radial
C _{ur}	480 N	Fatigue load limit, radial
	0,25 kg	Weight

Dimensions

C	18 mm	Width, outer ring
S	9 mm	Distance raceway
d ₁	39,4 mm	Rib diameter inner ring
d ₂	37,3 mm	Rib diameter sealing inner ring
A	5,8 mm	Distance thread
W	3 mm	Width of flats

Additional information

f ₀	13,8	Calculation factor
----------------	------	--------------------