



GE40-XL-KRR-B-2C


Radial insert ball bearing

Schaeffler ID:
0008285130000

Radial insert ball bearings GE...KRR-B-2C, spherical outer ring, location by eccentric locking collar, R seals on both sides

X-life

Technical information

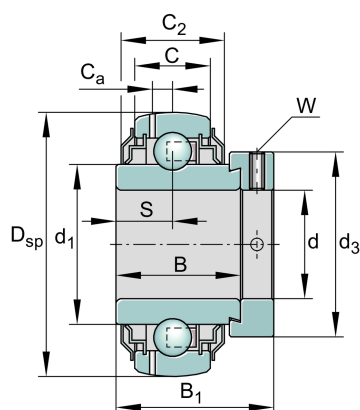

Main Dimensions & Performance Data

d	40 mm	Bore diameter
D _{SP}	80 mm	Outside diameter
B	42,9 mm	Width
B ₁	56,5 mm	Locking collar total width
n _{G Grease}	10.300 1/min	Limiting speed for grease lubrication
C _r	34.500 N	Basic dynamic load rating, radial
C _{0r}	19.800 N	Basic static load rating, radial
C _{ur}	1.030 N	Fatigue load limit, radial
	0,78 kg	Weight

Dimensions

C	21 mm	Width, outer ring
C ₂	31,9 mm	Sealing total width
S	21,4 mm	Distance raceway
d ₁	52,3 mm	Rib diameter inner ring
C _a	6,4 mm	Distance to lubrication hole
d ₃	58 mm	Outside diameter locking collar/locknut
W	5 mm	Width of flats

Calculation factors

f ₀	13,6	Calculation factor
----------------	------	--------------------