



★ GLE35-XL-KRR-B

Radial insert ball bearing


Schaeffler ID:
0008529020000

★ Preferred product

Radial insert ball bearings GLE..-KRR-B, spherical outer ring, non-locating bearing, drive slot in inner ring, R seals on both sides

X-life

Technical information

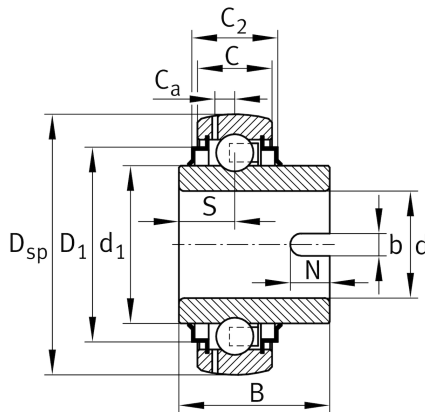

Main Dimensions & Performance Data

d	35 mm	Bore diameter
D _{SP}	72 mm	Outside diameter
B	37,7 mm	Width
n _{G Grease}	11.700 1/min	Limiting speed for grease lubrication
C _r	25.500 N	Basic dynamic load rating, radial
C _{0r}	15.300 N	Basic static load rating, radial
C _{ur}	700 N	Fatigue load limit, radial
	0,42 kg	Weight

Dimensions

C	19 mm	Width, outer ring
C ₂	22,5 mm	Sealing total width
S	15,7 mm	Distance raceway
d ₁	46,8 mm	Rib diameter inner ring
D ₁	60,3 mm	Outside diameter seal
C _a	5,6 mm	Distance to lubrication hole
N	8 mm	Height retaining slot
b	7 mm	Width retaining slot
	H11	Width retaining slot clearance

Additional information

f ₀	13,8	Calculation factor
----------------	------	--------------------